




Switches and Lighting Controls, Industrial Grade, Toggle Switches, Manual Motor Controller Accessories, Double Pole, 85A 600V AC, Side Wired Only

By Bryant  
Catalog # 85002D

Switches and Lighting Controls, Industrial Grade, Toggle Switches, Manual Motor Controller Accessories, Double Pole, 85A 600V AC, Side Wired Only, Black

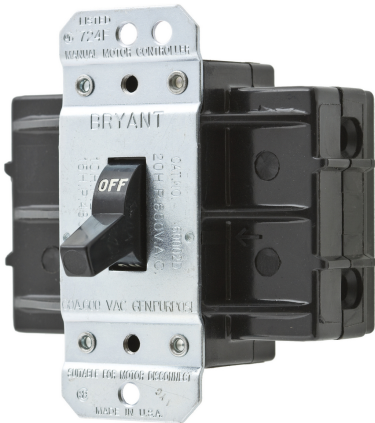

Features

- Toggle
- Manual Motor Controller Double Pole
- 85A 600V AC
- Side Wired Only

Specifications

|                          |                                                 |
|--------------------------|-------------------------------------------------|
| Environmental Conditions | Indoor Dry Unless Protected By Additional Means |
| EU RoHS Indicator        | Yes                                             |

Conductor

|                 |        |
|-----------------|--------|
| Number Of Poles | 2 Pole |
|-----------------|--------|

Current

|                            |                          |
|----------------------------|--------------------------|
| Phase                      | Single Phase             |
| Current / Amperage Rating  | 85 A                     |
| Connectivity               | Pressure Terminal Screws |
| Current Rating             | 85 A                     |
| Amperage Rating            | 85 A                     |
| Voltage Rating Description | 600V AC kV               |
| Wattage                    | 51000                    |
| Voltage Rating             | 600V AC kV               |

Dimensions

|              |                        |
|--------------|------------------------|
| Display Size | Standard Sized Product |
|--------------|------------------------|

Force Related

|               |           |
|---------------|-----------|
| Load Capacity | Inductive |
|---------------|-----------|

General

|                              |                             |
|------------------------------|-----------------------------|
| Item Type                    | Open Switch                 |
| Material - Mounting Hardware | Screw Mounting              |
| Type                         | Back Wire                   |
| Series                       | Standard Toggle             |
| OEM Brand Name               | Hubbell Bryant              |
| UPC                          | 781786631922                |
| Style                        | Motor Controller/Disconnect |

Logistics

|                 |    |
|-----------------|----|
| Carton Quantity | 10 |
|-----------------|----|

Operational

|                       |                                             |
|-----------------------|---------------------------------------------|
| Operating Cycles      | 10,000 Cycles Minimum                       |
| Operating Temperature | Minimum Continuous -40 Deg C without Impact |

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)