


**Straight Blade Devices, Male Plug, Heavy Duty, Industrial/Commercial Grade, Straight, 3-Pole 3-Wire Non-Grounding, 20A 125/250V, 10-20P, Single Pack**

By Bryant  
 Catalog # 9151N

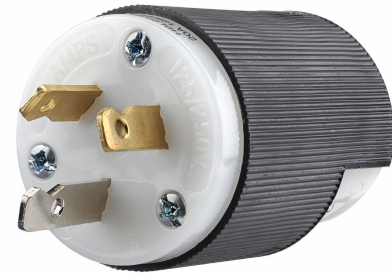

Straight Blade Devices, Male Plug, Heavy Duty, Industrial/Commercial Grade, Straight, 3-Pole 3-Wire Non-Grounding, 20A 125/250V, 10-20P, White, Single Pack

**Features**

- Heavy Duty
- Industrial/Commercial Grade
- Straight
- 3-Pole 3-Wire Non-Grounding
- 20A 125/250V

**Application**

Heavy Duty

**Specifications**

Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	No
Nema Rating	10-20P

**Conductor**

Number Of Wires	3-Wire
Wire Size	#14 AWG to #12 AWG
Number Of Poles	3-Pole

**Configuration**

Cord Type	All Portable
-----------	--------------

**Current**

Current Rating	20 A
Amperage Rating	20 A
Voltage Rating Description	250 V

Phase	Single Phase
Current / Amperage Rating	20 A
Connectivity	Screw Terminals
Wattage	5000
Voltage Rating	250 V

**Dimensions**

Display Size	Standard Sized
Length	2.50 in
Width	1.31 in
Weight	0.25 lb.

**General**

Series	Industrial
OEM Brand Name	Hubbell Bryant
Style	Heavy Duty
Color	Black and White
Item Type	Standard
Material - Mounting Hardware	Cord Mounted
Type	Plug
Material	Composite
UPC	781786631403

**Logistics**

Carton Quantity	10
-----------------	----

**Product Assets**

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)