



Straight Blade Devices, Receptacles, Flush Mount, Single, Commercial/Industrial Grade, Reinforced Thermoplastic Polyester, 30A 125/250V

By Bryant
Catalog # 9303

Straight Blade Devices, Receptacles, Flush Mount, Single, Commercial/Industrial Grade, Reinforced Thermoplastic Polyester, 30A 125/250V, 3-Pole 3-Wire Non-Grounding, 10-30R, Black, Single Pack.

Features

- Flush Mount
- Single
- Commercial/Industrial Grade
- Reinforced Thermoplastic Polyester
- 30A 125/250V

Specifications


Nema Rating 10-30R

Conductor

Number Of Poles 3-Pole
Number Of Wires 3 Wire

Current

Amperage Rating 30 A
Voltage Rating 125/250 VAC
Voltage Rating Description 125/250 VAC
Current / Amperage Rating 30 A

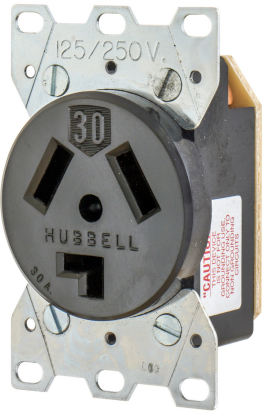

Current Rating 30 A

Dimensions

Weight 0.35 lb.

General

Color Black
Style Smooth Face
UPC 781786632233
Type Single Receptacle
Series Heavy Duty
OEM Brand Name Hubbell Bryant

Logistics

Carton Quantity 25

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)