



Locking Devices, Elastomeric, Male Plug, 20A 120/208V AC, 4-Pole 4-Wire Non-Grounding, Non-NEMA, Screw Terminal, Yellow, Water/Dust-Tight

By Bryant
Catalog # [BRY26W09](#)

Locking Devices, Elastomeric, Male Plug, 20A 120/208V AC, 4-Pole 4-Wire Non-Grounding, Non-NEMA, Screw Terminal, Yellow, Water/Dust-Tight

Features

- Triple bypass seal keeps water away from electrical connections and works with previously installed devices
- Corrosion-resistant connection points
- High conductivity brass termination
- Cone seal accomodates any cable range
- Keyed interior for easy installation

Specifications


Industry Standard(s)	IP69K
Nema Rating	Non-NEMA

Conductor

Number Of Wires	4-Wire
Wire Size	• Min. cords: #12/3 SJ, #16/3 S, #14/4 SJ, #18/4 S, #18/5 S • Max. cord: #8/3 S, #8/4 S, #10/5 S
Number Of Poles	4-Pole

Current

Current/Amperage Rating	20 Amp
Description	

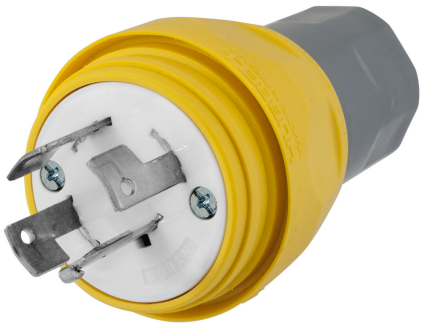

Amperage Rating	20 A
Voltage Rating Description	3 Phase Y 120/208 VAC
Voltage Rating	3 Phase Y 120/208 VAC

Dimensions

Width	2.51 in
Height	3.96 in
Length	2.51 in
Dimensions	2.51 in x 2.51 in x 3.96 in

General

Item Type	20A Watertight Plug
Type	Plugs
UPC	781786378377
Color	Yellow

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)