



Locking Devices, Elastomeric, Male Plug,
20A 3- Phase 120/208V AC, 4-Pole 4-Wire
Non-Grounding, Non-NEMA, Screw
Terminal, Water/Dust-Tight Housing

By Bryant
Catalog # [BRY28W09](#)

Locking Devices, Elastomeric, Male Plug, 20A 3- Phase 120/208V
AC, 4-Pole 4-Wire Non-Grounding, Non-NEMA, Screw Terminal,
Yellow, Water/Dust-Tight Housing

Features

- Triple bypass seal keeps water away from electrical connections and works with previously installed devices
- Corrosion-resistant connection points
- High conductivity brass termination
- Cone seal accomodates any cable range
- Keyed interior for easy installation

Performance


Dielectric voltage:2000V AC if rated 300V or less, 3000V AC if
rated above 300V, Moisture resistance:UL Listed to 3R, 3RX, 4,
4X, 6, 6P, 12, UV resistance:All exposed materials are UV
stabilized, Flammability:UL94V2 (plugs, connectors, and
interiors)

Specifications

Industry Standard(s)	• IP69K • Listed to UL498 • Certified to CSA C22.2 No. 42 • Meets NEMA® WD-1, WD-6, and ANSI Standards • IP66 Suitability • NSF Certified (plugs, connectors and receptacles)
Nema Rating	Non-NEMA

Conductor

Number Of Wires	4-Wire
Wire Size	• Min. cords: #12/3 SJ, #16/3 S, #14/4 SJ, #18/4 S, #18/5 S

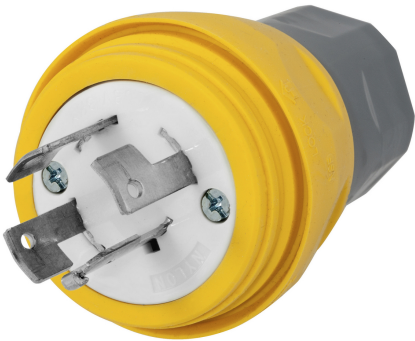

Number Of Poles	• Max. cord: #8/3 S, #8/4 S, #10/5 S 4-Pole
-----------------	---

Current

Current/Amperage Rating	30 Amp
Description	
Amperage Rating	30 A
Voltage Rating Description	3 Phase Y 120/208 VAC
Voltage Rating	3 Phase Y 120/208 VAC

Dimensions

Width	2.77 in
Height	3.94 in
Length	2.77 in
Dimensions	2.77 in x 2.77 in x 3.94 in

General

Item Type	30A Watertight Plug
Type	Plugs
UPC	781786378704
Color	Yellow

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)