




## Straight Blade Devices, Receptacles, Duplex, Commercial/Industrial Grade, Corrosion Resistant, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R, Brown

By Bryant  
Catalog # [BRY5262BCR](#)

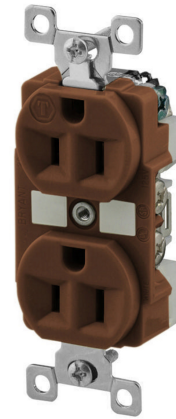

Straight Blade Devices, Receptacles, Duplex, Commercial/Industrial Grade, Corrosion Resistant, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R, Brown, Single Pack

### Features

- Duplex
- Commercial/Industrial Grade
- Corrosion Resistant
- 15A 125V
- 2-Pole 3-Wire Grounding

### Application

Extra Heavy Duty Industrial Specification Grade

### Specifications

Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	Yes
Nema Rating	5-15R

### Conductor

Number Of Wires	3-Wire
Wire Size	#14 AWG to #12 AWG
Number Of Poles	2-Pole

### Current

Current Rating	15 A
Amperage Rating	15 A
Voltage Rating Description	125 V
Phase	Single Phase
Current / Amperage Rating	15 A

Connectivity	Back and Side Wired
Wattage	1875
Voltage Rating	125 V

### Dimensions

Display Size	Standard Sized Product
Length	3.28 in
Width	1.54 in
Weight	0.25 lb.
Height	1.16 in
Dimensions	3.28 in x 1.54 in x 1.16 in

### General

Series	Extra Heavy Duty
OEM Brand Name	Hubbell Bryant
Style	Finder Groove Face
Color	Brown
Item Type	Traditional Duplex
Material - Mounting Hardware	Screw Mounting
Type	Duplex Receptacle
UPC	781786005099

### Logistics

Carton Quantity	10
-----------------	----

### Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)