



Straight Blade Device, Female Connector Body, Corrosion Resistant, Industrial/Commercial Grade, Straight, Corrosion Resistant

By Bryant
Catalog # [BRY5369NCCR](#)

Straight Blade Device, Female Connector Body, Corrosion Resistant, Industrial/Commercial Grade, Straight, 2- Pole 3-Wire Grounding, Yellow, Single Pack, Corrosion Resistant

Features

- Corrosion Resistant
- Industrial/Commercial Grade
- Straight
- 20A 125V
- 2- Pole 3-Wire Grounding

Application

Extra Heavy Duty Industrial Grade

Specifications

Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	Yes
Standards - RoHS Compliance Status	CM
Nema Rating	5-20R


Conductor

Number Of Wires	3-Wire
Number Of Conductors	3-Wire Grounding
Conductor Range	#14 AWG to #10 AWG
Number Of Poles	2-Pole

Current

Current Rating	20 A
Amperage Rating	20 A
Voltage Rating Description	125 V
Current / Amperage Rating	20 A
Connectivity	Screw Terminals
Voltage Rating	125 V

Dimensions

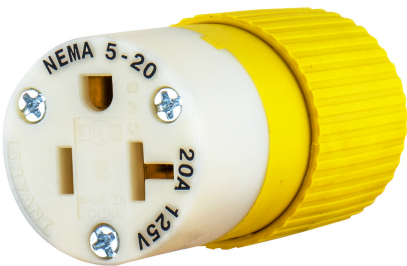

Display Size	Standard Sized Product
Length	2.95 in
Width	1.52 in
Weight	0.15 lb.
Height	1.38 in
Dimensions	2.95 in x 1.52 in x 1.38 in

General

Series	Industrial
OEM Brand Name	Hubbell Bryant
Cord Range	0.245"-0.655"
Style	Extra Heavy Duty
Color	Yellow
Item Type	Tech-Spec Triple Gripper
Insulation	Insulated Body
Material - Mounting Hardware	Cord Mounted
Type	Connector Body
Material	Composite
UPC	781786134140

Logistics

Carton Quantity	10
Pallet Quantity	5400

Operational

Temperature Rating	• Maximum Continuous: 75° C • Minimum Continuous: -40° C w/o impact, -25° with impact.
--------------------	--

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)