



Straight Blade Devices, Female Connector Body, Heavy Duty, Industrial/Commercial Grade, Straight, 20A 125V, 2-Pole 3- Wire Grounding, 5-20R

By Bryant
Catalog # [BRY5369NCSY](#)

Straight Blade Devices, Female Connector Body, Heavy Duty,
Industrial/Commercial Grade, Straight, 20A 125V, 2-Pole 3- Wire
Grounding, 5-20R, Yellow, Single Pack

Features

- Heavy Duty
- Industrial/Commercial Grade
- Straight
- 20A 125V
- 2-Pole 3- Wire Grounding

Application

Extra Heavy Duty Industrial Grade

Specifications

Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Nema Rating	5-20R


Conductor

Number Of Conductors	3-Wire Grounding
Number Of Wires	3-Wire
Number Of Poles	2-Pole
Conductor Range	#14 AWG to #10 AWG

Current

Amperage Rating	20 A
Voltage Rating Description	125 V
Current Rating	20 A
Voltage Rating	125 V
Connectivity	Screw Terminals
Current / Amperage Rating	20 A

Dimensions

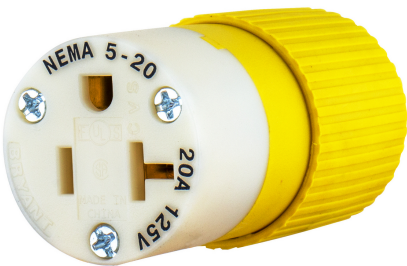

Length	2.95 in
Display Size	Standard Sized Product
Weight	0.1 lb.
Height	1.38 in
Width	1.52 in
Dimensions	2.95 in x 1.52 in x 1.38 in

General

Color	Yellow
Style	Extra Heavy Duty
Cord Range	0.245"-0.655"
Series	Industrial
OEM Brand Name	Hubbell Bryant
UPC	781786134157
Type	Connector Body
Material - Mounting Hardware	Cord Mounted
Insulation	Insulated Body
Item Type	Tech-Spec Triple Gripper
Material	Composite

Logistics

Carton Quantity	10
-----------------	----

Operational

Temperature Rating	• Maximum Continuous: 75° C • Minimum Continuous: -40° C w/o impact, -25° with impact.
--------------------	--

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)