


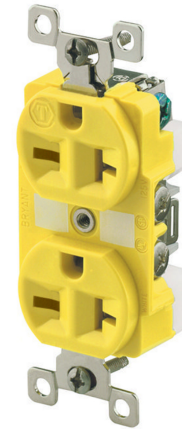

Straight Blade Devices, Receptacles, Duplex, Commercial/Industrial Grade, Corrosion Resistant, 20A 250V, 2-Pole 3-Wire Grounding, 6-20R, Single Pack

By Bryant
Catalog # [BRY5462CR](#)



Straight Blade Devices, Receptacles, Duplex, Commercial/Industrial Grade, Corrosion Resistant, 20A 250V, 2-Pole 3-Wire Grounding, 6-20R, Yellow, Single Pack

Features

- Duplex
- Commercial/Industrial Grade
- Corrosion Resistant
- 20A 250V
- 2-Pole 3-Wire Grounding

Application

Extra Heavy Duty Industrial Specification Grade

Specifications

Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	Yes
Standards - RoHS Compliance Status	CM
Nema Rating	6-20R

Conductor

Number Of Wires	3-Wire
Wire Size	#14 AWG to #12 AWG
Number Of Poles	2-Pole

Current

Current Rating	20 A
Amperage Rating	20 A
Voltage Rating Description	250 V
Phase	Single Phase

Current / Amperage Rating	20 A
Connectivity	Back and Side Wired
Wattage	5000
Voltage Rating	250 V

Dimensions

Display Size	Standard Sized Product
Length	3.28 in
Width	1.54 in
Weight	0.2 lb.
Height	1.16 in
Dimensions	3.28 in x 1.54 in x 1.16 in

General

Series	Extra Heavy Duty
OEM Brand Name	Hubbell Bryant
Style	Finder Groove Face
Color	Yellow
Item Type	Traditional Duplex
Material - Mounting Hardware	Screw Mounting
Type	Duplex Receptacle
UPC	781786005419

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)