



Straight Blade Devices, Receptacles,
Duplex, Commercial/Industrial Grade, 20A
125V and 250V, 2-Pole 3-Wire Grounding,
5-20R and 6- 20R, Brown

By Bryant
Catalog # [BRY5492](#)

Straight Blade Devices, Receptacles, Duplex,
Commercial/Industrial Grade, 20A 125V and 250V, 2-Pole 3-Wire
Grounding, 5-20R and 6- 20R, Brown, Single Pack

Features

- Duplex
- Commercial/Industrial Grade
- 20A 125V and 250V
- 2-Pole 3-Wire Grounding
- 5-20R and 6- 20R

Application

Extra Heavy Duty Industrial Specification Grade

Specifications


Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	Yes
Standards - RoHS Compliance Status	CM
Nema Rating	5-20R, 6-20R

Conductor

Number Of Wires	3-Wire
Wire Size	#14 AWG to #12 AWG
Number Of Poles	2-Pole

Current

Current Rating	20 A
Amperage Rating	20 A
Voltage Rating Description	125/250 V
Phase	Single Phase

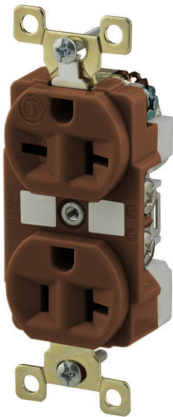

Current / Amperage Rating	20 A
Connectivity	Back and Side Wired
Wattage	5000
Voltage Rating	125/250 V

Dimensions

Display Size	Standard Sized Product
Length	3.28 in
Width	1.54 in
Weight	0.25 lb.
Height	1.16 in
Dimensions	3.28 in x 1.54 in x 1.16 in

General

Series	Heavy Duty
OEM Brand Name	Hubbell Bryant
Style	Finder Groove Face
Color	Brown
Item Type	Traditional Duplex
Material - Mounting Hardware	Screw Mounting
Type	Combination Receptacle
UPC	781786005433

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)