



Twist-Lock® Devices, Watertight Series, Receptacle, Duplex, 15A 277V AC, 2-Pole 3-Wire Grounding, L7-15R, Yellow

By Bryant
Catalog # [BRY65W34D](#)

Twist-Lock® Devices, Watertight Series, Receptacle, Duplex, 15A 277V AC, 2-Pole 3-Wire Grounding, L7-15R, Yellow

Features


- Impact-resistant PBT material lid and cover plate
- Stainless steel mounting hardware
- Lockable cover meets OSHA Lockout/Tagout regulations
- Thermoplasticelastomer seal

Performance

Moisture resistance: UL Listed to 3R, 3RX, 4, 4X, wet and damp locations (portable outlet boxes), UV resistance:All exposed materials are UV stabilized, Flammability:UL94V0 (boxes, covers, and plates)

Specifications

Industry Standard(s)	• IP69K in use • Listed to UL498 • Certified to CSA C22.2 No. 42 • Meets NEMA® WD-1, WD-6, and ANSI Standards • IP66 Suitability • NSF Certified (plugs, connectors and receptacles)
Nema Rating	L7-15R

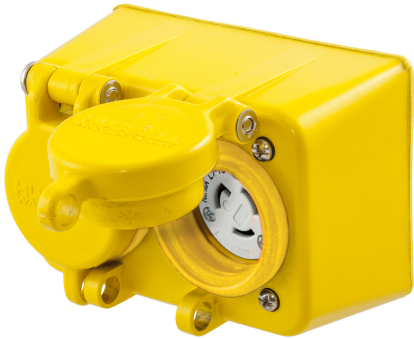

Conductor

Number Of Wires	3-Wire
Wire Size	#18 AWG to #10 AWG
Number Of Poles	2-Pole

Current

Current/Amperage Rating	15 Amp
Description	
Amperage Rating	15 A
Voltage Rating Description	277 VAC
Voltage Rating	277 VAC

General

Item Type	15A Watertight Duplex Receptacle
Type	Duplex Receptacle
UPC	781786380349
Color	Yellow

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)