



Straight Blade Devices, Receptacles,
Tamper- Resistant Duplex, Hospital Grade,
15A 125V, 2-Pole 3-Wire Grounding, 5- 15R,
Ivory, Single Pack

By Bryant
Catalog # [BRY8200ITR](#)

Straight Blade Devices, Receptacles, Tamper- Resistant Duplex,
Hospital Grade, 15A 125V, 2-Pole 3-Wire Grounding, 5- 15R, Ivory,
Single Pack

Features

- Tamper- Resistant Duplex
- Hospital Grade
- 15A 125V
- 2-Pole 3-Wire Grounding
- 5- 15R

Application

Hospital Grade

Specifications


Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	No
Nema Rating	5-15R

Conductor

Number Of Wires	3-Wire
Wire Size	#14 AWG to #12 AWG
Number Of Poles	2-Pole

Current

Current Rating	15 A
Amperage Rating	15 A
Voltage Rating Description	125 V
Phase	Single Phase
Current / Amperage Rating	15 A
Connectivity	Back and Side Wired

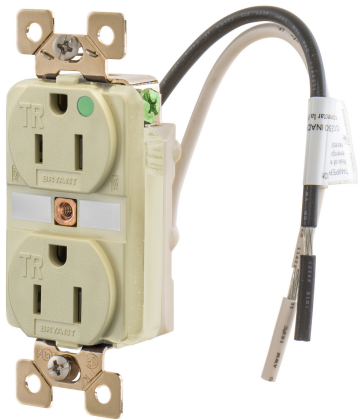

Wattage	1875
Voltage Rating	125 V

Dimensions

Display Size	Standard Sized Product
Length	3.28 in
Width	1.65 in
Weight	0.35 lb.
Height	2.75 in
Dimensions	3.28 in x 1.65 in x 2.75 in

General

Series	Hospital Grade
OEM Brand Name	Hubbell Bryant
Style	Finder Groove Face
Color	Ivory
Item Type	Traditional Duplex
Material - Mounting Hardware	Screw Mounting
Type	Duplex Receptacle
Material	Composite
UPC	781786005761

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)