




Straight Blade Devices, Receptacles, Duplex, Hospital Grade, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R, Red, Single Pack, Illuminated Face

By Bryant
Catalog # [BRY8200REDL](#)

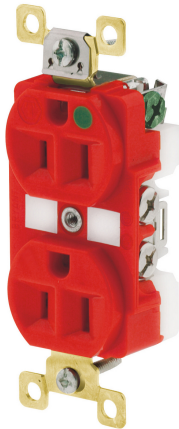

Straight Blade Devices, Receptacles, Duplex, Hospital Grade, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R, Red, Single Pack, Illuminated Face

Features

- Duplex
- Hospital Grade
- 15A 125V
- 2-Pole 3-Wire Grounding
- 5-15R

Application

Hospital Grade

Specifications

Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	Yes
Nema Rating	5-15R

Conductor

Number Of Wires	3-Wire
Wire Size	#14 AWG to #12 AWG
Number Of Poles	2-Pole

Current

Current Rating	15 A
Amperage Rating	15 A
Voltage Rating Description	125 V
Phase	Single Phase
Current / Amperage Rating	15 A
Connectivity	Back and Side Wired

Wattage	1875
Voltage Rating	125 V

Dimensions

Display Size	Standard Sized Product
Length	3.28 in
Width	1.54 in
Weight	0.2 lb.
Height	1.16 in
Dimensions	3.28 in x 1.54 in x 1.16 in

General

Series	Hospital Grade
OEM Brand Name	Hubbell Bryant
Style	Finder Groove Face
Color	Red
Item Type	Traditional Duplex
Material - Mounting Hardware	Screw Mounting
Type	Duplex Receptacle
Material	Composite
UPC	781786005624

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)