



Straight Blade Devices, Receptacles,  
Tamper- Resistant Duplex, Hospital Grade,  
15A 125V, 2-Pole 3-Wire Grounding, 5- 15R,  
Red, Single Pack

By Bryant  
Catalog # [BRY8200RTR](#)

Straight Blade Devices, Receptacles, Tamper- Resistant Duplex,  
Hospital Grade, 15A 125V, 2-Pole 3-Wire Grounding, 5- 15R, Red,  
Single Pack

Features

- Tamper- Resistant Duplex
- Hospital Grade
- 15A 125V
- 2-Pole 3-Wire Grounding
- 5- 15R

Application

Hospital Grade

Specifications


|                          |                                                    |
|--------------------------|----------------------------------------------------|
| Environmental Conditions | Indoor Dry Unless Protected By<br>Additional Means |
| EU RoHS Indicator        | No                                                 |
| Nema Rating              | 5-15R                                              |

Conductor

|                 |                    |
|-----------------|--------------------|
| Number Of Wires | 3-Wire             |
| Wire Size       | #14 AWG to #12 AWG |
| Number Of Poles | 2-Pole             |

Current

|                            |                     |
|----------------------------|---------------------|
| Amperage Rating            | 15 A                |
| Voltage Rating Description | 125 V               |
| Current Rating             | 15 A                |
| Voltage Rating             | 125 V               |
| Wattage                    | 1875                |
| Connectivity               | Back and Side Wired |

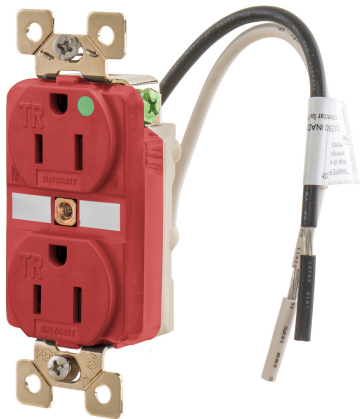

|                           |              |
|---------------------------|--------------|
| Phase                     | Single Phase |
| Current / Amperage Rating | 15 A         |

Dimensions

|              |                             |
|--------------|-----------------------------|
| Length       | 3.28 in                     |
| Display Size | Standard Sized Product      |
| Weight       | 0.35 lb.                    |
| Height       | 2.75 in                     |
| Width        | 1.65 in                     |
| Dimensions   | 3.28 in x 1.65 in x 2.75 in |

General

|                              |                    |
|------------------------------|--------------------|
| Color                        | Red                |
| Style                        | Finder Groove Face |
| Series                       | Hospital Grade     |
| OEM Brand Name               | Hubbell Bryant     |
| UPC                          | 781786005785       |
| Type                         | Duplex Receptacle  |
| Material - Mounting Hardware | Screw Mounting     |
| Item Type                    | Traditional Duplex |
| Material                     | Composite          |

Logistics

|                 |    |
|-----------------|----|
| Carton Quantity | 10 |
|-----------------|----|

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)