



Straight Blade Devices, Receptacles,
Tamper- Resistant Duplex, Hospital Grade,
20A 125V, 2-Pole 3-Wire Grounding, 5-
20R, Red, Single Pack

By Bryant
Catalog # [BRY8300RTR](#)

Straight Blade Devices, Receptacles, Tamper- Resistant Duplex,
Hospital Grade, 20A 125V, 2-Pole 3-Wire Grounding, 5- 20R, Red,
Single Pack

Features

- Tamper- Resistant Duplex
- Hospital Grade
- 20A 125V
- 2-Pole 3-Wire Grounding
- 5- 20R

Application

Hospital Grade

Specifications


Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	No
Nema Rating	5-20R

Conductor

Number Of Wires	3-Wire
Wire Size	#14 AWG to #12 AWG
Number Of Poles	2-Pole

Current

Amperage Rating	20 A
Voltage Rating Description	125 V
Current Rating	20 A
Voltage Rating	125 V
Wattage	2500
Connectivity	Back and Side Wired
Phase	Single Phase

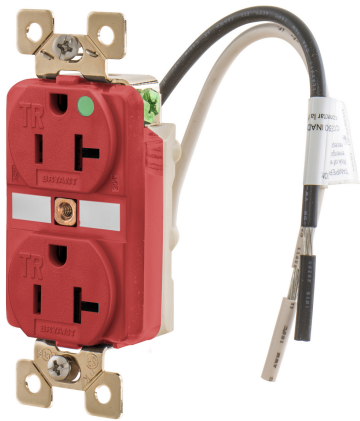

Current / Amperage Rating	20 A
Dimensions	
Length	3.28 in
Display Size	Standard Sized Product
Weight	0.35 lb.
Height	2.75 in
Width	1.65 in
Dimensions	3.28 in x 1.65 in x 2.75 in

General

Color	Red
Style	Finder Groove Face
Series	Hospital Grade
OEM Brand Name	Hubbell Bryant
UPC	781786005839
Type	Duplex Receptacle
Material - Mounting Hardware	Screw Mounting
Item Type	Traditional Duplex
Material	Composite

Logistics

Pallet Quantity	4000
Carton Quantity	10

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)