



Locking Devices, Locking Devices, Industrial, Receptacle, 50A 250V, 2-Pole 3-Wire Grounding, Non-NEMA, Screw Terminal, Black

By Bryant  
Catalog # CS8269A

Locking Devices, Locking Devices, Industrial, Receptacle, 50A 250V, 2-Pole 3-Wire Grounding, Non-NEMA, Screw Terminal, Black

Features

- Thermoset construction offers high heat resistance
- Armored housing provides superior impact resistance
- One piece contacts provide low operating temperatures

Application

Extra Heavy Duty Industrial Specification Grade

Specifications


|                          |                                                 |
|--------------------------|-------------------------------------------------|
| Environmental Conditions | Indoor Dry Unless Protected By Additional Means |
| EU RoHS Indicator        | No                                              |
| Industry Standard(s)     | WR Rating                                       |

Conductor

|                 |                    |
|-----------------|--------------------|
| Number Of Wires | 3-Wire             |
| Wire Size       | #14 AWG to #10 AWG |
| Number Of Poles | 2-Pole             |

Current

|                            |                          |
|----------------------------|--------------------------|
| Current/Amperage Rating    | 50 Amp                   |
| Description                |                          |
| Current Rating             | 50 A                     |
| Amperage Rating            | 50 A                     |
| Voltage Rating Description | 250V AC                  |
| Phase                      | Single Phase             |
| Connectivity               | Pressure Terminal Screws |

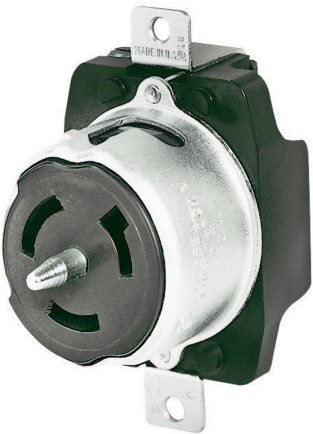

|                |                             |
|----------------|-----------------------------|
| Voltage Rating | 250 VAC                     |
| Dimensions     |                             |
| Display Size   | Standard Sized Product      |
| Length         | 3.28 in                     |
| Width          | 2.12 in                     |
| Height         | 2.44 in                     |
| Dimensions     | 3.28 in x 2.12 in x 2.44 in |

General

|                              |                                          |
|------------------------------|------------------------------------------|
| OEM Brand Name               | Hubbell Bryant                           |
| Style                        | Extra Heavy Duty                         |
| Color                        | Black                                    |
| Item Type                    | 50A Single Armored Heavy Duty Receptacle |
| Material - Mounting Hardware | Screw Mounting Receptacle                |
| Type                         | Receptacle                               |
| Material                     | Composite                                |
| UPC                          | 781786253315                             |

Logistics

|                 |    |
|-----------------|----|
| Carton Quantity | 10 |
|-----------------|----|

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)