



Straight Blade Devices, Commercial Grade,
Decorator Duplex, Weather and Tamper
Resistant, 20A 125V, 2-Pole 3-Wire
Grounding, 5-20R, Light Almond

By Bryant
Catalog # [DRS20LAWRTR](#)

Straight Blade Devices, Commercial Grade, Decorator Duplex,
Weather and Tamper Resistant, 20A 125V, 2-Pole 3-Wire
Grounding, 5-20R, Light Almond

Features

- Decorator Duplex
- Weather and Tamper Resistant
- 20A 125V
- 2-Pole 3-Wire Grounding
- 5-20R

Application

Commercial Grade

Specifications


Environmental Conditions	Weather Resistant
EU RoHS Indicator	No
Nema Rating	5-20R

Conductor

Number Of Wires	3-Wire
Wire Size	#14 AWG to #12 AWG
Number Of Poles	2-Pole

Current

Current Rating	20 A
Amperage Rating	20 A
Voltage Rating Description	125 V
Phase	Single Phase
Current / Amperage Rating	20 A

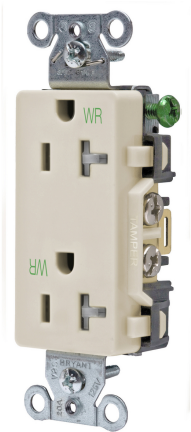

Connectivity	Back and Side Wired Terminal Screws
Wattage	2500
Voltage Rating	125 V

Dimensions

Display Size	Standard Sized Product
Weight	0.25 lb.

General

Series	Commercial
OEM Brand Name	Hubbell Bryant
Style	Decorator
Color	Light Almond
Item Type	Decorator Duplex
Material - Mounting Hardware	Screw Mounting
Type	Duplex Receptacle
Material	Composite
UPC	781786141674

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog \[English\]](#)
[Catalog Page \[English\]](#)