




Lampholders, Fluorescent Starter, 13-30-40W

By Bryant
Catalog # [FS4A](#)

Lampholders, Fluorescent Starter, 13-30-40W

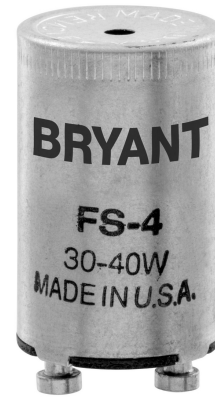

Features

- 13-30-40W

Application

Low Wattage Fluorescent

Specifications

EU RoHS Indicator No

Current

Frequency Rating 60 Hz
Wattage 13, 30, 40W
Voltage Rating 120/277V AC kV

General

Item Type Fluorescent Starters
Material - Mounting Hardware Plug-In

Type	Neostart
Series	Fluorescent Starters
OEM Brand Name	Hubbell Bryant
Lamp Type	Pre-Heat
UPC	781786689725
Color	White

Logistics

Carton Quantity 25

Operational

Minimum Starting Temperature 40 Degrees F °
Start Type Neo-Start

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)