


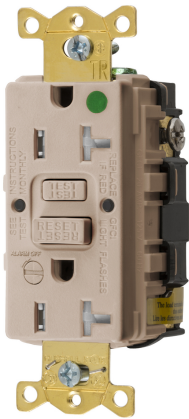

Receptacle, 20A, Comm, HG, Seft test,
Tamper Resistant, Alarm, GFR, Almond

By Bryant
Catalog # [GFST83ALTRB](#)

Receptacle, 20A, Comm, HG, Seft test, Tamper Resistant, Alarm,
GFR, Almond



Features

- Comm
- HG
- Seft test
- Tamper Resistant
- Alarm

Specifications

Nema Rating5-20R

Conductor

Number Of Wires3-Wire
Number Of Poles2-Pole

Current

Current / Amperage Rating20 A
Amperage Rating20 A
Voltage Rating Description125 V
Voltage Rating125 V

General

TypeHeavy Duty
SeriesHospital Grade
UPC781786390249
StyleTamper-Resistant
ColorAlmond

Logistics

Carton Quantity25