




Metal Raceway, 5' Cover, HBL2000 Series, Ivory

By Bryant
Catalog # [HBL2000CIV](#)

Metal Raceway, 5' Cover, HBL2000 Series, Ivory

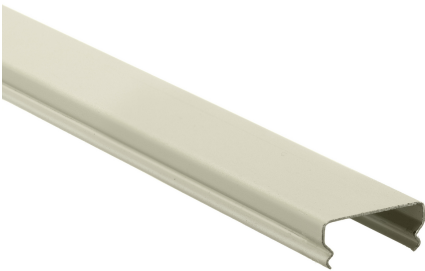

Features

- Higher capacity power applications
- Available in cover only or base and cover options
- Cover is 0.040 Inch (1.016) thick which allows up to 600V AC

Performance

Electrical - Rating - 300V Rated

Specifications

Industry Standard(s)	• CSA Standard C22.2 no. 62 • E253976 /E253830 /E253833 • UL Standard UL 5
EU RoHS Indicator	Contact Manufacturer

Dimensions

Length	5 ft
--------	------

General

Item Type	HBL2000 Series
-----------	----------------

Type	Cover Only
Enclosure Type	NEMA 1 Rating
Series	• HBL2000 • HBL2000A
Material	Steel
Specifications	• Channel Area (sq. in.) - 0.89 • Cover Thickness - 0.025 in. (0.635) • Material - Galvanized Steel
UPC	783585214092
Style	Single Channel
Color	Ivory

Logistics

Carton Quantity	50
-----------------	----

Product Assets

- [Catalog \[English\]](#)
- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)