

1) Three Way Switch 1) Pilot Light Clear

Features

- Smooth, quiet rocker
- Low profile, less than 1 inch deep
- Self-grounding feature is standard
- Residential Grade

Ordering Information

| Color        | UPC          | Catalog Number |
|--------------|--------------|----------------|
| Light Almond | 883778300806 | RCD309LA       |

Listings


CSA Certified  
UL Listed E3896

Specifications

|                          |                                                           |
|--------------------------|-----------------------------------------------------------|
| Action                   | Snap Switch                                               |
| Contact Configuration    | Two Position                                              |
| Environmental Conditions | Indoor Dry Unless Protected By Additional Means           |
| Operating Cycles         | 30,000 Minimum                                            |
| Operating Temperature    | Max Continuous- 60 Degrees C, Minimum- -20 Without Impact |
| Wattage                  | 1875                                                      |

Performance

|                        |                                                                                                                                |
|------------------------|--------------------------------------------------------------------------------------------------------------------------------|
| <b>Electrical</b>      |                                                                                                                                |
| Dielectric voltage     | Withstands 1,500V AC minimum for 1 minute                                                                                      |
| Endurance              | 30,000 cycles minimum                                                                                                          |
| Max. working voltage   | 120V                                                                                                                           |
| Overload               | 1.5 times rating                                                                                                               |
| <b>Mechanical</b>      |                                                                                                                                |
| Terminal accommodation | Back and side wire: #14 AWG min. - #12 AWG max. solid and stranded copper wire only; push wire: #14 AWG solid copper wire only |
| <b>Environmental</b>   |                                                                                                                                |
| Flammability           | UL V-0                                                                                                                         |
| Operating Temperatures | Maximum continuous 60°C; minimum -20°C (without impact)                                                                        |

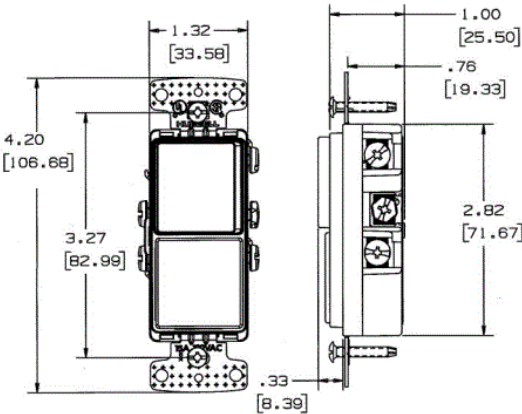

Online Resources

Customer Sales Drawings  
eCatalog  
Installation Instructions

