


Kellems Wire Managent, Cord Connector,
Non-Metallic, .37-.50", 3/4", Gray

By Hubbell Wiring Device-Kellems
Catalog # [HBL10CM35S](#)

Kellems® Cord Connector Non-Metallic .37-.50", 3/4"

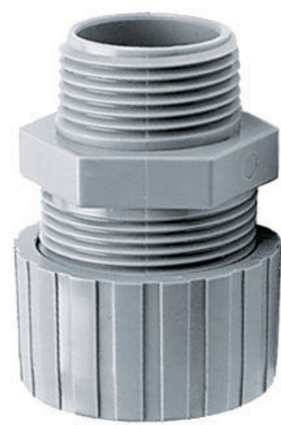

Features

- Strain relief and a Watertight seal

Application

Straight Male

Specifications

Environmental Conditions	Suitable For Use In Wet Locations When Used With A Listed Nylon Washer Between Box And Fitting.
EU RoHS Indicator	Yes
Standards - RoHS Compliance Status	CM

Conductor

Number Of Conductors	Single
Conductor Range	0.38-0.5 in (9.5-12.7 mm)

Dimensions

Display Size	3/4" NPT
--------------	----------

General

OEM Brand Name	Hubbell Wiring Device-Kellems
Color	Gray
Material - Mounting Hardware	Locknut or Tapped Opening
Material	Nylon
Specifications	• Diameter Range - .38 - .50 in. (9.5 - 12.7) • Hub Size - 3/4 in. NPT • Product Type - Cord Connectors
UPC	783585808031

Logistics

Carton Quantity	10
-----------------	----

Operational

Temperature Rating	Minimum -30 Deg F to 225 Deg F (-43 Deg C to 107 Deg C)
--------------------	---

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)