


Kellems Wire Managent, Cord Connector,
Non-Metallic, .62-.75", 1", Gray

By Hubbell Wiring Device-Kellems
Catalog # [HBL10CM41S](#)

Kellems® Cord Connector Non-Metallic .62-.75", 1"

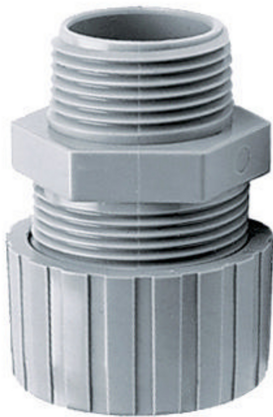

Features

- Strain relief and a Watertight seal

Application

Straight Male

Specifications

Environmental Conditions	Suitable For Use In Wet Locations When Used With A Listed Nylon Washer Between Box And Fitting.
EU RoHS Indicator	Yes

Conductor

Conductor Range	0.63-0.75 in (15.9-19.1 mm)
Number Of Conductors	Single

Dimensions

Display Size	1" NPT
--------------	--------

General

Material - Mounting Hardware	Locknut or Tapped Opening
OEM Brand Name	Hubbell Wiring Device-Kellems
Material	Nylon
Specifications	• Diameter Range - .63 - .75 in. (15.9 -19.1) • Hub Size - 1.0 in. NPT • Product Type - Cord Connectors
UPC	783585808062
Color	Gray

Logistics

Carton Quantity	10
-----------------	----

Operational

Temperature Rating	Minimum -30 Deg F to 225 Deg F (-43 Deg C to 107 Deg C)
--------------------	---

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)