

Features


- Spring rewind and ratchet lock
- Multi-position four roller guide and adjustable hose stop
- Full flow shafts and swivels assure maximum product delivery

Ordering Information

Description	UPC Number	Catalog Number
Low pressure 1/2" ID	783585243658	HBLHR5035

Specifications

Cable Length Feet (m)	35 (10.7)
Max Pressure Psi	300
Frame Size	C
Input Hose Fitting (NPTF)	3/8
O.D. Inch (mm)	0.77 (19.6)
Weight Lbs. (kg)	38 (17.2)

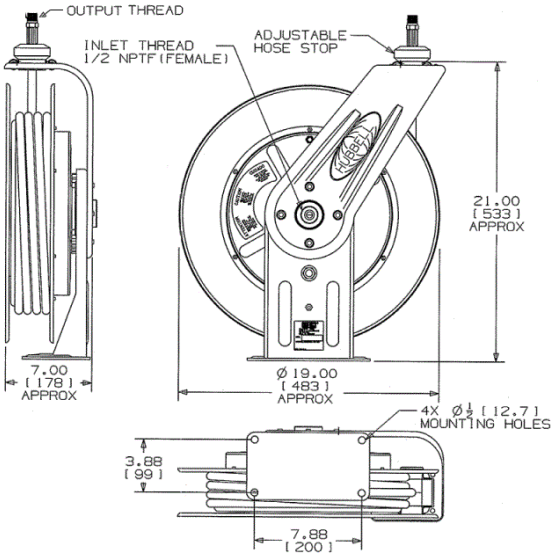

Online Resources

- Customer Sales Drawings
- eCatalog
- Installation Instructions