


HUBBELL Premise Wiring

Non-Metallic Raceway, BaseTrak Series, 2 Channel Cover, 10' Length

By Hubbell Premise Wiring
Catalog # [PB2C10](#)

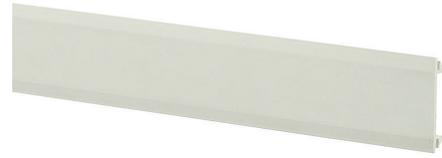

Non-Metallic Raceway BaseTrak, 2 Channel Cover, 10'

Features

- UL Listed and CSA Certified to 600 volts
- Single and two channel latching raceways are dual-rated for both power and data applications, reducing inventory requirements

Performance

Environmental - Flame Rating - UL94V-0, Environmental - Temperature Range - -25.6° to 158° F

Specifications

Non Hazardous Location Industry Standard(s)	Non Hazardous <ul style="list-style-type: none">• CSA Standard C22.2 no. 62• E118895 / E119190• UL Standard UL 5A
EU RoHS Indicator	Yes

Configuration

Knockouts	None
-----------	------

Dimensions

Width	4.5 in
Length	10 ft

General

Item Type	PB2, 2-Channel BaseTrak
Construction	Extruded Plastic
Type	Cover Only
Enclosure Type	NEMA 1 Rating
Series	PB2
Cover Type	Removable
Material	Thermoplastic
Specifications	<ul style="list-style-type: none">• Crush Resistance - 300 lbs.• Impact Resistance - 5 ft. lbs.• Length - 10 ft. (3m)• Material - UV Stabilized PVC
UPC	783585310022
Style	Two Channel
Color	Office White

Logistics

Carton Quantity	60
-----------------	----

Product Assets

- [Catalog \[English\]](#)
- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)