


HUBBELL

Premise Wiring

6119PCL12

By Hubbell Premise Wiring
Catalog # [6119PCL12](#)

Patch Cord, 6-110 Factory Terminated Patch Cords, Cat6, T568B
(6-110 to RJ45), 12' Length

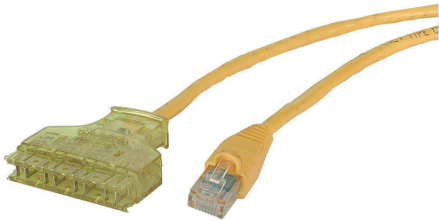

Features

- Plug Housing Includes Built-In Polarization to Ensure Proper Mating Connection to Connecting Blocks
- Angled Conductor Towers Separate Paired Conductors and makes Pair Splitting and Conductor Lacing Simple
- Cable Ties Secure Cable to Cover for Easy Termination and Strain Relief

Specifications

Industry Standard(s)	Exceeds TIA/EIA-568-C.2-1 Category 6 ConNEcting Hardware SpecifiCations
EU RoHS Indicator	Yes

Conductor

Conductor Type	Copper
Conductor Stranding	Stranded
Number Of Conductors	8-Conductor
Wire Size	#26-22 AWG

Current

Voltage Rating	600V AC kV
----------------	------------

Dimensions

Outside Diameter	0.218
------------------	-------

General

Specifications	Material - Polycarbonate UL 94V-0
UPC	662620835969
Plug Type	110 Punch Down
Material - Jacket	Flame Redardant PVC
Material - Insulation	Flame Redardant PVC

Logistics

Carton Quantity	20
-----------------	----

Operational

Temperature Rating	Per TIA
--------------------	---------