


HUBBELL

Premise Wiring

Copper Solutions, Cable, Cat6, Foil Twisted Pair, 10 Gig, Plenum Rated, Spool, Gray

By Hubbell Premise Wiring
Catalog # [C6FTPSPGY](#)

Copper Solutions, Cable, Cat6, Foil Twisted Pair, 10 Gig, Plenum Rated, Spool, Gray

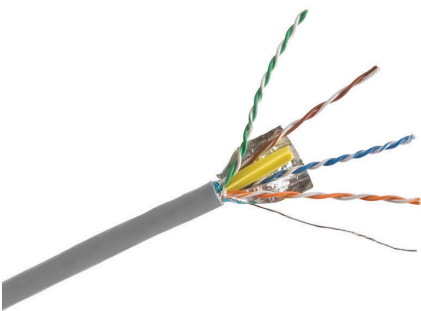

Features

- Cat6
- Foil Twisted Pair
- 10 Gig
- Plenum Rated
- Spool

Application

Plenum

Specifications

EU RoHS Indicator Yes

Conductor

Nema Color Gray
Conductor Type Solid Bare Copper
Pairs Or Conductor 4-Pair

Configuration

Debris Shield Type Foil Tape

Current

Impedance 100

General

UPC 662620288116
Material - Jacket Low Smoke PVC
OEM Brand Name Hubbell Premise Wiring

Logistics

Carton Quantity 1000

Operational

Data Transfer Rate 1GbE, Limited 10GbE
Temperature Rating -20oC to +50oC (-4oF to +122oF)

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)