

Floor Boxes

SystemOne ETERNAL™ Series Concrete Floorboxes

8/10-Gang Recessed

HUBBELL

Features

- 3.75" deep wiring chambers for large AV modules and feed-thru capacity
- External High Capacity Feed-Thru Hubs Sold Separately
- Stamped steel construction, ships with Flush Installation Cover & 1/2" Prepour Cover
- Pre and post pour adjustment
- Rectangular cover, labor saving easy mount device plates

Ordering Information

Cover Style	Box Type	Catalog Number	UPC Number
Rectangular	Above Grade	CFB10G55E	783585695112

Listings

cULus Listed
UL 514A Listed

Specifications

Box Material	16 gauge galvanized steel
Box Finish	Natural
Top Mousing Plates	16 gauge galvanized steel
Flush Prepour Cover	16 gauge galvanized steel
1/2" Prepour Cover	Yellow Plastic
Device Chamber Grounding	6" Long #12 AWG Solid Copper Wire
Wiring Chamber Depth	3.75"
Wiring Chamber Volumes	(2) Small 35 IN³ [574 CM³], (2) Med 69.5 IN³ [1139 CM³], (2) Large 99 IN³ [1622 CM³]

Performance

Height

5.59" [142.0mm]

Length


14.14" [359.2mm]

Trade Size Knock-Outs: Ends

(2) ½", ¾", (4) 1½", ¾", 1", 1¼", 1½"

Width

11.09" [281.6mm]

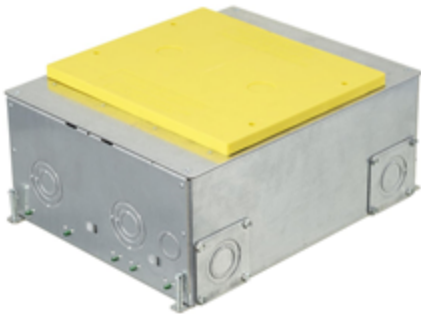

Accessories

(2) 2"PVC field installed hubs, ships with (2) 1-1/2" reducer, (2) 1-1/4" reducers, and (2) 1" reducers/plugs	CFBHUB200PVC
(2) 1-1/4" PVC field installed hubs, ships with (2) 1" reducers, (2) 3/4" reducers, AND (2) 1/2" reducer/plugs	CFBHUB125PVC
2" threaded zinc hub	CFBHUB2
Rectangular pre-pour ½ in. extension caps (2 pack)	610GEXTENDCAP2PK
(1) SyleLine Decorater Opening	FB10MPREC

Online Resources

Customer Sales Drawings
eCatalog
Installation Instructions

