


7-Gang CFB Series Box for Rectangular
Covers, 4.08" Minumum Depth of Pour

By Hubbell Premise Wiring
Catalog # [CFB7G4](#)

7-Gang CFB Box for Rectangular Cover, 4.08" Minumum Depth of
Pour

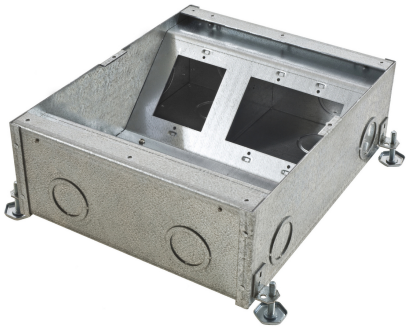

Features

- Recessed 7-Gang Round Cover Floorbox
- For Use In Concrete Floors
- 4.08" Minimum Depth of Pour
- Box Includes Installation Cover
- Accepts industry Standard Size Wallplates

Application

For Use in Concrete Floors

Specifications

Industry Standard(s)	• UL/CSA • UL514
EU RoHS Indicator	No

Conductor

Cable Entry	Through Cover
-------------	---------------

Configuration

Knockouts	11) 1" - 1 1/2" , 1) 2"
Mounting Method	Cast Into Concrete
Number of Gang(s)	7-Gang

Dimensions

Size	7-Gang
Width	12.08 in
Height	4.08 in
Length	10 in
Dimensions	10 in x 12.08 in x 4.08 in

General

Construction	Fabricated
Type	7-Gang Recessed Floor Box
Series	Recessed Rectangular - CFB Series
Material	Pre Galvanized Steel
Specifications	Min. Depth of Pour - 4.08" (103.5)
UPC	783585315881
Application - For Use On	Concrete
Color	Metallic

Logistics

Carton Quantity	1
Pallet Quantity	90

Product Assets

[Catalog \[English\]](#)
[Catalog \[English\]](#)
[Catalog Page \[English\]](#)