


7-Gang CFB Series Box for Rectangular  
Covers, 6.08" Minumum Depth of Pour

By Hubbell Premise Wiring  
Catalog # [CFB7G6](#)

7-Gang CFB Box for Rectangular Cover, 6.08" Minumum Depth of  
Pour

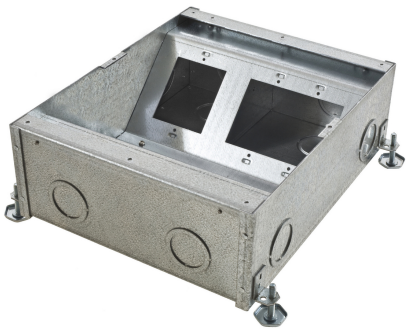

Features

- Recessed 7-Gang Round Cover Floorbox
- For Use In Concrete Floors
- 4.08" Minimum Depth of Pour
- Box Includes Installation Cover
- Accepts industry Standard Size Wallplates

Application

For Use in Concrete Floors

Specifications

|                      |                                                                          |
|----------------------|--------------------------------------------------------------------------|
| Industry Standard(s) | <ul style="list-style-type: none"><li>• UL/CSA</li><li>• UL514</li></ul> |
| EU RoHS Indicator    | No                                                                       |

Conductor

|             |               |
|-------------|---------------|
| Cable Entry | Through Cover |
|-------------|---------------|

Configuration

|                   |                                        |
|-------------------|----------------------------------------|
| Knockouts         | 4) 1" - 1 1/4", 7) 1" - 1 1/2" , 1) 2" |
| Mounting Method   | Cast Into Concrete                     |
| Number of Gang(s) | 7-Gang                                 |

Dimensions

|            |                            |
|------------|----------------------------|
| Size       | 7-Gang                     |
| Width      | 12.16 in                   |
| Height     | 6.08 in                    |
| Length     | 10 in                      |
| Dimensions | 10 in x 12.16 in x 6.08 in |

General

|                          |                                    |
|--------------------------|------------------------------------|
| Construction             | Fabricated                         |
| Type                     | 7-Gang Recessed Floor Box          |
| Series                   | Recessed Rectangular - CFB Series  |
| Material                 | Pre Galvanized Steel               |
| Specifications           | Min. Depth of Pour - 6.08" (154.3) |
| UPC                      | 783585315898                       |
| Application - For Use On | Concrete                           |
| Color                    | Metallic                           |

Logistics

|                 |   |
|-----------------|---|
| Carton Quantity | 1 |
|-----------------|---|

Product Assets

- [Catalog \[English\]](#)  
[Catalog \[English\]](#)  
[Catalog Page \[English\]](#)  
[Catalog Page \[English\]](#)