


HUBBELL
Premise Wiring

Fiber Optic, Riser Rated, OM4 Duplex, LC-SC, 5 Meter Length

By Hubbell Premise Wiring
Catalog # [DFHRCLCSCF5MM](#)

Fiber Optic, Riser Rated, OM4 Duplex, LC-SC, 5 Meter Length

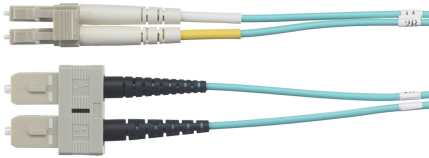

Features

- Bend insensitive fiber

Application

Fiber Data Cross Connect

Specifications

- | | |
|----------------------|--|
| Industry Standard(s) | <ul style="list-style-type: none">• EIA/TIA-455/-604• TIA-568-C.3 |
|----------------------|--|

Conductor

- | | |
|------------|-----------|
| Mode | multimode |
| Fiber Type | OM4 |

Dimensions

Length (Meters)	5 m
-----------------	-----

General

Color	Aqua
UPC	662620360850
Sub Brand	FIBERHUBB

Logistics

Carton Quantity	25
-----------------	----

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)