

FiberHUBB™


Rack Mount Enclosure

MPO UltraMax LC Duplex Frame

HUBBELL

Features

- Straight and Angled Panel Versions
- Easy-Slide Labeling System with Template
- Detachable Cable Management Bar
- MPO Male Input with up to 144 LC Output Ports
- Custom Adapter Colors and Port Counts Available

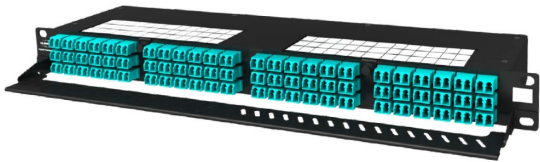

Ordering Information

Description	Total LC	Catalog Number	UPC
MPO UltraMax, Straight Front, OM4, 144 Ports, Aqua	144	FHD1U144LC12MP4	662620367637

Listings

EIA/ECA-310-E
TIA.569-D
RoHS Compliant

Specifications

Adapter Color	Aqua
Connectivity	MPO to LC Duplex
Material - Enclosure	Cold-Rolled Steel
Dimensions	1.73 (44) x 17.65 (448) x 8.48 (215)
Fiber Type	OM4
LC Duplex Adapters	72
Total LC Ports	144
MPO Connector Type	Male, 12-Port
Total MPO Connectors	12
Polarity Type	A

Accessories

Rear Fiber Management Bar	HPRCMB
---------------------------	--------

Online Resources

eCatalog