


HUBBELL
Premise Wiring

Fiber, Pigtail, Bundle, 250 Micron, Buffered
Loose Tube, SC-Multi Mode, 12-Fiber
Strands, OM1 Fiber, 3 MeterLength

By Hubbell Premise Wiring
Catalog # [FHPBKLTR12SC4M](#)

Fiber, Pigtail, Bundle, 250 Micron, Buffered Loose Tube, SC-Multi
Mode, 12-Fiber Strands, OM1 Fiber, 3 MeterLength

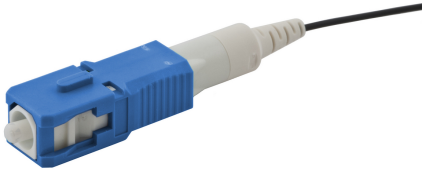

Features

- Bundle
- 250 Micron
- Buffered Loose Tube
- SC-Multi Mode
- 12-Fiber Strands

Application

Optical Signal

Conductor

Conductor Type	Glass
Wire Type	Multimode
Wire Size	50 Micron

Current

Connectivity	Plug-In
--------------	---------

Dimensions

Length	118.11 in
Pitch	12

Outside Diameter	0.2
------------------	-----

General

Color	Aqua
UPC	662620363073
Plug Type	SC-MM, 12F, 250LT, OM4
Material	Glass Fiber
Material - Jacket	Flame Redardant PVC
Material - Insulation	Flame Redardant PVC

Logistics

Carton Quantity	50
-----------------	----

Operational

Temperature Rating	TIA 568-C.3
--------------------	-------------

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)