


HUBBELL
Premise Wiring

Fiber, Pigtail, Bundle, 250 Micron, Buffered
Loose Tube, SC-A, Single Mode, 12-Fiber
Strands, OS2 Fiber, 3Meter Length.

By Hubbell Premise Wiring
Catalog # [FHPBKLTR12SCA6S](#)

Hubbell Premise Wiring Products, Fiber, Pigtail, Bundle, 250
Micron,Buffered Loose Tube, SC-A, Single Mode, 12-Fiber Strands,
OS2 Fiber, 3Meter Length.

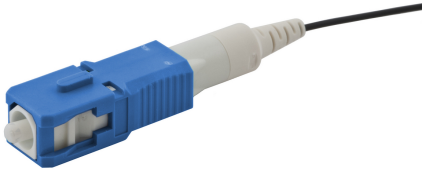

Features

- Bundle
- 250 Micron
- Buffered Loose Tube
- SC-A
- Single Mode

Application

Optical Signal

Conductor

Number Of Fibers	12
Conductor Type	Glass
Mode	OS2
Fiber Type	Riser
Wire Type	Multimode
Wire Size	9 Micron

Current

Connectivity	Plug-In
--------------	---------

Dimensions

Length (Meters)	3 m
Pitch	12
Outside Diameter	0.2

General

UPC	662620363097
Plug Type	SC-A-SM, 12F, 250LT, OS2
Material	Glass Fiber
Material - Jacket	Flame Redardant PVC
Material - Insulation	Flame Redardant PVC

Logistics

Carton Quantity	50
-----------------	----

Operational

Temperature Rating	TIA 568-C.3
--------------------	-------------

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)