


HUBBELL
Premise Wiring

Fiber, Pigtail, Bundle, LC-Multi Mode, 12-Fiber Strands, OM3 Fiber, 3 Meter Length

By Hubbell Premise Wiring
Catalog # [FHPBKR12LC3M](#)

Fiber, Pigtail, Bundle, LC-Multi Mode, 12-Fiber Strands, OM3 Fiber, 3 Meter Length

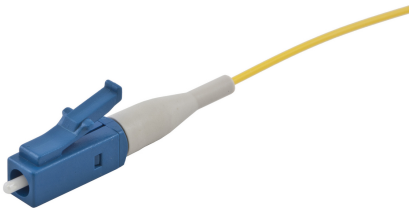

Features

- Bundle
- LC-Multi Mode
- 12-Fiber Strands
- OM3 Fiber
- 3 Meter Length

Application

Optical Signal

Conductor

Number Of Fibers	12
Conductor Type	Glass
Mode	OM3
Fiber Type	Riser
Wire Type	Multimode
Wire Size	50 Micron

Current

Connectivity	Plug-In
--------------	---------

Dimensions

Length (Meters)	3 m
Pitch	12
Outside Diameter	0.2

General

UPC	662620363226
Plug Type	LC-MM, 12F, OM3
Material	Glass Fiber
Material - Jacket	Flame Redardant PVC
Material - Insulation	Flame Redardant PVC

Logistics

Carton Quantity	50
-----------------	----

Operational

Temperature Rating	TIA 568-C.3
--------------------	-------------

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)