


HUBBELL
Premise Wiring

Fiber, Pigtail, Bundle, LC-Multi Mode, 6-
Fiber Strands, OM4 Fiber, 3 Meter

By Hubbell Premise Wiring
Catalog # [FHPBKR6LC4M](#)

Fiber, Pigtail, Bundle, LC-Multi Mode, 6-Fiber Strands, OM4 Fiber,
3 Meter

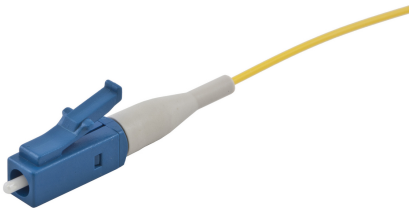

Features

- Bundle
- LC-Multi Mode
- 6-Fiber Strands
- OM4 Fiber
- 3 Meter

Application

Optical Signal

Conductor

Conductor Type	Glass
Wire Type	Multimode
Wire Size	50 Micron

Current

Connectivity	Plug-In
--------------	---------

Dimensions

Length	118.11 in
Pitch	6

Outside Diameter	0.2
------------------	-----

General

Color	Aqua
UPC	662620363370
Plug Type	LC-MM, 6F, OM4
Material	Glass Fiber
Material - Jacket	Flame Redardant PVC
Material - Insulation	Flame Redardant PVC

Logistics

Carton Quantity	50
-----------------	----

Operational

Temperature Rating	TIA 568-C.3
--------------------	-------------

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)