


HUBBELL  
Premise Wiring

Fiber, Pigtail, Bundle, SC-Single Mode, 6-  
Fiber Strands, OS2 Fiber, 3 Meter

By Hubbell Premise Wiring  
Catalog # [FHPBKR6SC6S](#)

Fiber, Pigtail, Bundle, SC-Single Mode, 6-Fiber Strands, OS2  
Fiber, 3 Meter

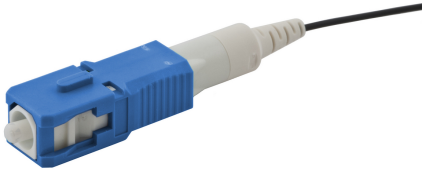

Features

- Bundle
- SC-Single Mode
- 6-Fiber Strands
- OS2 Fiber
- 3 Meter

Application

Optical Signal

Conductor

|                |           |
|----------------|-----------|
| Conductor Type | Glass     |
| Wire Type      | Multimode |
| Wire Size      | 9 Micron  |

Current

|              |         |
|--------------|---------|
| Connectivity | Plug-In |
|--------------|---------|

Dimensions

|        |           |
|--------|-----------|
| Length | 118.11 in |
| Pitch  | 6         |

|                  |     |
|------------------|-----|
| Outside Diameter | 0.2 |
|------------------|-----|

General

|                       |                     |
|-----------------------|---------------------|
| Color                 | Yellow              |
| UPC                   | 662620363431        |
| Plug Type             | SC-SM, 6F, OS2      |
| Material              | Glass Fiber         |
| Material - Jacket     | Flame Redardant PVC |
| Material - Insulation | Flame Redardant PVC |

Logistics

|                 |    |
|-----------------|----|
| Carton Quantity | 50 |
|-----------------|----|

Operational

|                    |             |
|--------------------|-------------|
| Temperature Rating | TIA 568-C.3 |
|--------------------|-------------|

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)