


HUBBELL
Premise Wiring

Fiber, Pigtail, Bundle, 250 Micron, Buffered
Loose Tube, LC-Multi Mode, 12-Fiber
Strands, OM4 Fiber, 3 MeterLength

By Hubbell Premise Wiring
Catalog # [FPBKLTR12LC4M](#)

Fiber, Pigtail, Bundle, 250 Micron, Buffered Loose Tube, LC-Multi
Mode, 12-Fiber Strands, OM4 Fiber, 3 MeterLength

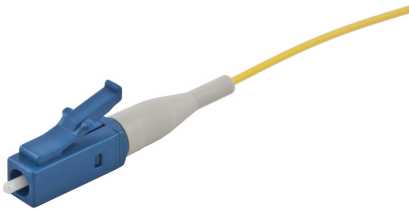

Application

Optical Signal

Specifications

EU RoHS Indicator Yes

Conductor

Number Of Fibers 12
Conductor Type Glass
Mode OM4
Fiber Type Riser
Wire Type Multimode
Wire Size 50 Micron

Current

Connectivity Plug-In

Dimensions

Length (Meters) 3 m
Pitch 12
Outside Diameter 0.2

General

UPC 662620308746
Plug Type LC-MM, 12F, 250LT, OM4
Material Glass Fiber
Material - Jacket Flame Redardant PVC
Material - Insulation Flame Redardant PVC

Logistics

Carton Quantity 50

Operational

Temperature Rating TIA 568-C.3