


HUBBELL
Premise Wiring

Fiber, Pigtail, Bundle, SC-Multi Mode, 12-
Fiber Strands, OM3 Fiber, 3 Meter Length

By Hubbell Premise Wiring
Catalog # [FPBKR12SC3M](#)

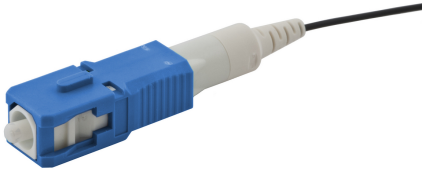

Fiber, Pigtail, Bundle, SC-Multi Mode, 12-Fiber Strands, OM3 Fiber,
3 Meter Length

Application

Optical Signal

Specifications

EU RoHS Indicator Yes

Conductor

Number Of Fibers 12
Mode OM3
Wire Type Multimode
Wire Size 50 Micron
Conductor Type Glass
Fiber Type Riser

Current

Connectivity Plug-In

Dimensions

Length (Meters) 3 m
Pitch 12
Outside Diameter 0.2

General

Plug Type SC-MM, 12F, OM3
UPC 662620306414
Material Glass Fiber
Material - Jacket Flame Redardant PVC
Material - Insulation Flame Redardant PVC

Logistics

Carton Quantity 50

Operational

Temperature Rating TIA 568-C.3