

Mounted Zone Cabling Enclosures and Brackets

Industrial ReBox Enclosure with Equipment Mounting Brackets

NEMA 4/12 ReBox Enclosure Configured for Cooling

HUBBELL

Features

- Continuous plasma-welded seams provide a seal to protect equipment from water intrusion
- Modular backboard systems eliminates time consuming field engineering
- Flexible mounting solutions for active equipment and UPS

Ordering Information

NEMA Rating	Finish	Catalog Number	UPC Number
4 / 12	Gray powder coated	IR211AFK	662620606330

Listings

NEMA Rated 4 / 12
EIA/ECA-310-E Universal Mounting Pattern
UL Listed

Specifications

Material	Cold rolled steel
Gauge	14
Finish	Light gray
NEMA Rating	4 / 12
Rail Type	#12-24 Threaded
Rack Units	2

Characteristics


NEMA Rating	4 / 12
Rack Units	2

Accessories

2000 BTU AC	IRAC2
1U Power strip	HPWPWR
Black Velcro Roll	HVFBK575
#12-24 Screws	1224RRSCRW20
Cement Anchor Kit	HPWRR

Online Resources

eCatalog

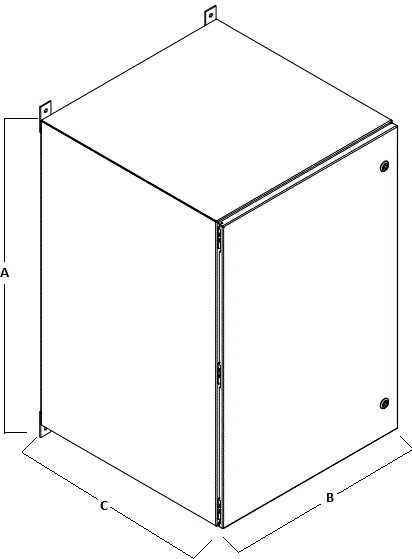

Dimensions- inches (mm)

A	24" (610)
B	14" (356)
C	16" (406)