


# HUBBELL Premise Wiring

## Non-Metallic Raceway, BaseTrak Series, Base and Cover, 10' Length

By Hubbell Premise Wiring  
Catalog # [PB3BC10](#)

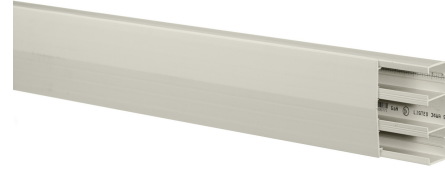

Non-Metallic Raceway, BaseTrak Series, Base and Cover, 10'  
Length

### Features

- UL Listed and CSA Certified to 600 volts
- Single and two channel latching raceways are dual-rated for both power and data applications, reducing inventory requirements

### Application

10' Base and Cover

### Performance

Environmental - Flame Rating - UL94V-0, Environmental -  
Temperature Range - -25.6° to 158° F

### Specifications

Non Hazardous Location	Non Hazardous
Industry Standard(s)	<ul style="list-style-type: none"><li>• CSA Standard C22.2 no. 62</li><li>• E118895 / E119190</li><li>• UL Standard UL 5A</li></ul>
EU RoHS Indicator	Yes

### Configuration

Knockouts	None
-----------	------

### Dimensions

Width	4.5 in
Length	10 ft

### General

Item Type	PB3, 3-Channel BaseTrak
Construction	Extruded Plastic
Type	Base and Cover
Enclosure Type	NEMA 1 Rating
Series	PB3
Cover Type	Removable
Material	Thermoplastic
Specifications	<ul style="list-style-type: none"><li>• Crush Resistance - 300 lbs.</li><li>• Impact Resistance - 5 ft. lbs.</li><li>• Length - 10 ft. (3m)</li><li>• Material - UV Stabilized PVC</li></ul>

UPC	783585090764
Style	Three Channel
Color	Office White

### Logistics

Carton Quantity	60
-----------------	----

### Product Assets

- [Catalog \[English\]](#)
- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)