


HUBBELL
Premise Wiring

Copper Solutions, Patch Cord, Cat6A,
10GHz, Shielded, Blue, 40' Length

By Hubbell Premise Wiring
Catalog # [PC6AB40](#)

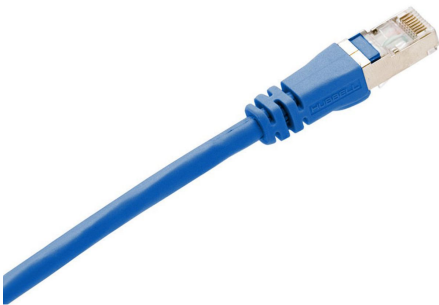

Copper Solutions, Patch Cord, Cat6A, 10GHz, Shielded, Blue, 40'
Length

Features

- Cat6A
- 10GHz
- Shielded
- Blue
- 40' Length

Application

Category 6A

Specifications

EU RoHS Indicator Yes

Conductor

Conductor Type Copper
Conductor Stranding Stranded
Number Of Conductors 8-Conductor

Wire Size #24 AWG

Current

Voltage Rating 300V AC kV

Dimensions

Outside Diameter 0.218

General

Color Blue
UPC 662620215198
Plug Type RJ45
Material - Jacket Flame Redardant PVC
Material - Insulation Flame Redardant PVC
OEM Brand Name Hubbell Premise Wiring

Operational

Temperature Rating Per TIA