


HUBBELL  
Premise Wiring

PC6AOR07

By Hubbell Premise Wiring  
Catalog # [PC6AOR07](#)

Copper Solutions, Patch Cord, Cat6A, 10GHz, Shielded, Orange,  
7' Length

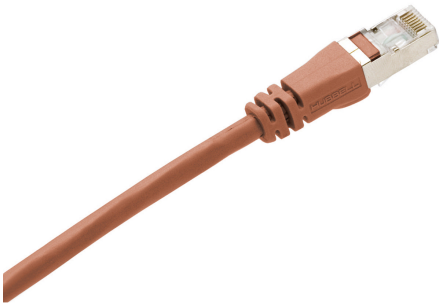

Application

Category 6A

Specifications

EU RoHS Indicator                      Yes

Conductor

Conductor Type                      Copper  
Conductor Stranding                Stranded  
Number Of Conductors              8-Conductor  
Wire Size                              #24 AWG

Current

Voltage Rating                      300V AC kV

Dimensions

Outside Diameter                      0.218

General

Color                                      Orange  
UPC                                        662620204512  
Plug Type                                RJ45  
Material - Jacket                      Flame Redardant PVC  
Material - Insulation                Flame Redardant PVC

Logistics

Carton Quantity                      100

Operational

Temperature Rating                Per TIA