


Non-Metallic Raceway, Latching WallTrak,
WallTRAK2, Base and Cover, 5'Length

By Hubbell Premise Wiring
Catalog # [PW2BC5](#)

Non-Metallic Raceway Latching WallTrak, WallTRAK2,Base and
Cover, 5'Length

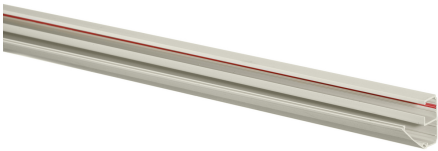

Features

- UL Listed and CSA Certified to 600 volts
- Single and two channel latching raceways are dual-rated for both power and data applications, reducing inventory requirements

Application

5' Base and Cover

Performance

Environmental - Flame Rating - UL94V-0, Environmental -
Temperature Range - -25.6° to 158° F

Specifications

Non Hazardous Location	Non Hazardous
Industry Standard(s)	• CSA Standard C22.2 no. 62 • E118895 / E119190 • UL Standard UL 5A
EU RoHS Indicator	Yes

Configuration

Knockouts	None
-----------	------

Dimensions

Width	2.12 in
-------	---------

Length	5 ft
--------	------

General

Item Type	PW2, 2-Channel WallTrak-Latching
Construction	Extruded Plastic
Type	Base and Cover
Enclosure Type	NEMA 1 Rating
Series	PW2
Cover Type	Removable
Material	Thermoplastic
Specifications	• Crush Resistance - 300 lbs. • Impact Resistance - 5 ft. lbs. • Length - 5 ft. (1.5m) • Material - UV Stabilized PVC

UPC	783585090610
Style	Two Channel, Latching
Color	Office White

Logistics

Carton Quantity	50
-----------------	----

Product Assets

- [Catalog \[English\]](#)
- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)