

2-Gang Rectangular Flanges



Features

- Solid Brass Rectangular Flat Flange with Beveled Edges and Brushed Finish
- Beveled Edges Provides a Soother Transition to Hard Finished Surfaces
- Low Profile, 0.125" Height
- Includes (2) 6" #12 AWG Grounding Wires
- Meets ADA standards for accessible design

Ordering Information

Flange Style	Box Type	UPC	Catalog Number
Rectangular	Rectangular	783585696423	SB3084WB

Listings

cULus Listed
ADA compliant flange


Specifications

Flange Material	Brushed Brass
Device Spacer Material	Thermoplastic
Flange Grounding	6" Long #12 AWG Solid Copper Wire

Performance

Mechanical

Flange Height	.125" [3.2mm]
Flange Length	4.85" [116.3mm]
Flange Width	8.13" [206.5mm]

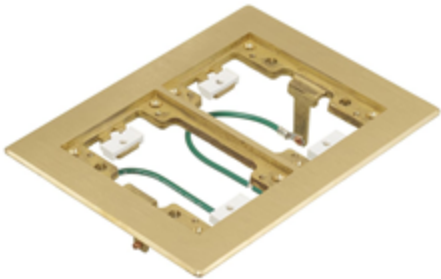

Related Products

Duplex Flap Brass Cover	S3825
StyleLine® Flap Brass Cover	S3826
Duplex Screw Brass Cover	S3625
2-1/8" x 1" Combo Brass Cover	S2625

Online Resources

Customer Sales Drawings
eCatalog
Installation Instructions

