

- Features
- Stainless steel mesh is corrosion resistant
 - Multiweave grip gives cable arc-of-bend control
 - Endless weave provides easy cable/flexible conduit installation

Ordering Information

Description	Form Size	Cable	UPC	Catalog Number
90° Male Thread, Liquidtight, for Insulated Cables	F4	.875"-1.000" (2.22-2.54)	783585322728	07401091

- Listings
- UL Listed


CSA Certified

Specifications

Strand	Stainless Steel
Body	Aluminum

Performance

Environmental	UL 94HB (Strand grip), UL 94V-2(Fitting)
Flammability	Suitable for use in hazardous locations per Class I Div. 2, Class II Div. 1 & 2, Class III Div. 1 & 2 N.E.C
Hazardous Locations	
Operating Temperatures	−30°F to +240°F (−34°C to +115°C)
Wet Locations	Suitable for use in wet locations when used with a listed sealing ring between box and fitting

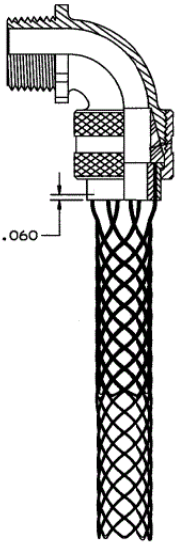

Related Products

Locknut	00322003LPK50
Metal Clad Sealing O-Ring	20509003

- Online Resources
- Customer Sales Drawings

eCatalog

Installation Instructions