

Kellems® Wire Management Products
PG and Metric Threaded Deluxe Cord Grips
Deluxe Cord Grips

HUBBELL

Features

- Aluminum Fiting
- Stainless steel mesh is corrosion resistant
- Neoprene bushing is oil and watertight

Ordering Information

Description	Hub Size	Cable	UPC	Catalog Number
Straight Metric Male Thread, Liquidtight	M32	.750"-.875" (1.90-2.22)	783585327877	074M32023

Listings


UL Listed
 CSA Certified

Specifications

Strand	Stainless Steel
Body	Aluminum

Performance

Environmental	
Flammability	UL 94HB (Strand grip), UL 94V-2 (Fitting)
Hazardous Locations	Suitable for use in hazardous locations per Class I Div. 2, Class II Div. 1 & 2, Class III Div. 1 & 2 N.E.C
Operating Temperatures	-30°F to +240°F (-34°C to +115°C)
Wet Locations	Suitable for use in wet locations when used with a listed sealing ring between box and fitting

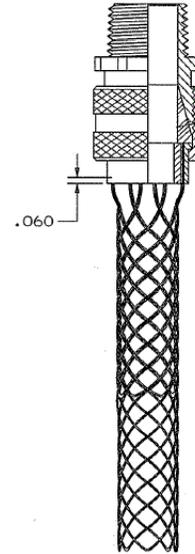

Related Products

Locknut	LNM32BPK100
---------	-------------

Online Resources

- Customer Sales Drawings
- eCatalog
- Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

