

Deluxe Cord Grips

Features

- Aluminum Fiting
- Stainless steel mesh is corrosion resistant
- Neoprene bushing is oil and watertight

Ordering Information

Description	Hub Size	Cable	UPC	Catalog Number
Straight Panzergewinde Male Thread, Liquidtight	PG29	1.125"-1.250" (2.86-3.17)	783585327853	074PG291028

Listings

UL Listed
CSA Certified

Specifications

Strand	Galvanized Steel
Body	Aluminum


Performance

Environmental

Flammability UL 94HB (Strand grip), UL 94V-2 (Fitting)
Hazardous Locations Suitable for use in hazardous locations per Class I Div. 2, Class II Div. 1 & 2, Class III Div. 1 & 2 N.E.C

Operating Temperatures -30°F to +240°F (-34°C to +115°C)
Wet Locations Suitable for use in wet locations when used with a listed sealing ring between box and fitting

HUBBELL

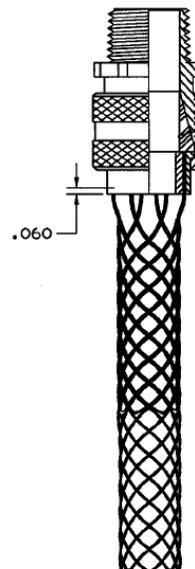

Related Products

Locknut

LNP29BPK100

Online Resources

Customer Sales Drawings
eCatalog
Installation Instructions