



## Power Protection Devices, Receptacle, Self Test, GFCI, 20A 125V, 2-Pole 3-Wire Grounding, 5-20R, Almond

By Bryant  
Catalog # [GFRST20AL](#)

Power Protection Devices, Receptacle, Self Test, GFCI, 20A 125V,  
2-Pole 3-Wire Grounding, 5-20R, Almond

### Features

- Patented AUTOGUARD® self test technology
- Internal back wiring clamp and guide for quick and secure termination
- Triple wipe construction


### Specifications

Industry Standard(s)	Meets All NEC® Requirements
Nema Rating	5-20R

### Current

Current / Amperage Rating	20 A
Amperage Rating	20 A
Voltage Rating Description	125 V

### General

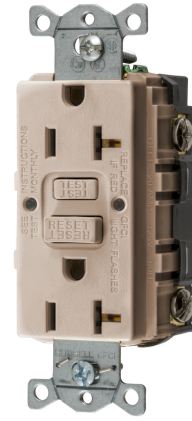

Type  
Series  
Specifications

Standard  
Heavy Duty

- Base - Nylon
- Face - Nylon
- Ground Contacts - Brass
- Mounting Screws - Zinc plated steel
- Mounting Strap - Zinc plated steel
- Power Contacts - Brass

UPC  
Style  
Color

883778122088  
Standard  
Almond

### Logistics

Carton Quantity 10