




## Power Protection Products, Receptacle, GFCI, Commercial Grade, Self Test, 20A 125V, 2-Pole 3-Wire Grounding, 5- 20R, With Nightlight, Almond

By Bryant

Catalog # [GFRST20ALNL](#)

Power Protection Products, Receptacle, GFCI, Commercial Grade, Self Test, 20A 125V, 2-Pole 3-Wire Grounding, 5- 20R, With Nightlight, Almond

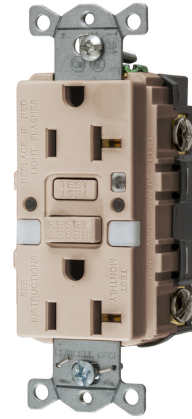

### Features

- Patented AUTOGUARD® self test technology
- Internal back wiring clamp and guide for quick and secure termination
- Triple wipe construction
- Includes light sensor controls for automatic on and off, custom dual lens for optimum light output

### Specifications

Industry Standard(s)	Meets All NEC® Requirements
EU RoHS Indicator	Contact Manufacturer
Nema Rating	5-20R

### Current

Current / Amperage Rating	20 A
Amperage Rating	20 A
Voltage Rating Description	125 V

### General

Type	Standard
Series	Heavy Duty
Specifications	<ul style="list-style-type: none"><li>• Base - Nylon</li><li>• Face - Nylon</li><li>• Ground Contacts - Brass</li><li>• Mounting Screws - Zinc plated steel</li><li>• Mounting Strap - Zinc plated steel</li><li>• Power Contacts - Brass</li></ul>
UPC	883778123283
Style	Nightlight
Color	Almond

### Logistics

Carton Quantity	10
-----------------	----